

# CD45SL2GA470J-VKA

--- Disc Type Capacitors with Lead ---



## Application & Main Feature


Commercial Grade (Safety Standard Approved)

## Series

CD45 Series

## Dimensions

D	8.0mm Max.
T	6.0mm Max.
F	10.0mm +/-1.0mm
d	0.6mm +/-0.05mm

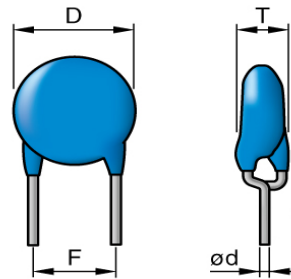

## Temperature Characteristic

SL(+350 to -1000ppm/degC)

## Rated Voltage

400Vac

## Withstanding Voltage

4000Vac

## Capacitance

47pF

## Capacitance Tolerance

+/-5%

## Dissipation Factor

0.5% Max.

## Insulation Resistance

10000Mhorm Min.

## AEC-Q200

Not Applicable

## Lead Length / Package Type

Taping

