

CD12ZU2GA472MYGKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature

Commercial Grade (Safety Standard Approved)

Series

CD Series

Dimensions

| | |
|---|--------------------|
| D | 13.5mm Max. |
| T | 7.0mm Max. |
| F | 10.0mm +2.0,-1.0mm |
| d | 0.6mm +/-0.05mm |
| ℓ | 21.0mm Min. |



Temperature Characteristic

Z5U(+22,-56%)

Rated Voltage

440Vac

Withstanding Voltage

4000Vac

Capacitance

4.7nF

Capacitance Tolerance

+/-20%

Dissipation Factor

2.5% Max.

Insulation Resistance

10000Mohm Min.


AEC-Q200

Not Applicable


Lead Length / Package Type

25mm for Bulk

|Z| vs. Freq. Characteristic

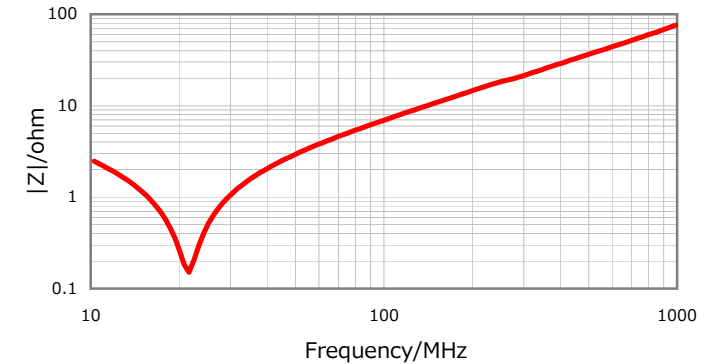

Temperature Characteristic

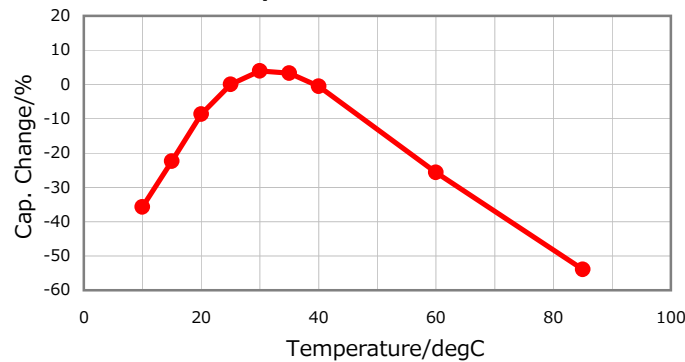

Leak Current

