

CD45-B2GA331K-GKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature


Commercial Grade (Safety Standard Approved)

Series

CD45 Series

Dimensions

D	7.0mm Max.
T	6.0mm Max.
F	10.0mm +2.0,-1.0mm
d	0.6mm +/-0.05mm
ℓ	21.0mm Min.

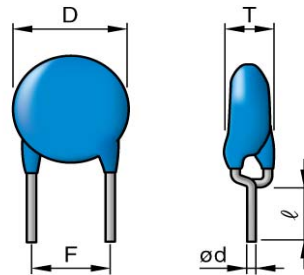

Temperature Characteristic

B(+/-10%)

Rated Voltage

400Vac

Withstanding Voltage

4000Vac

Capacitance

330pF

Capacitance Tolerance

+/-10%

Dissipation Factor

2.5% Max.

Insulation Resistance

10000Mhorm Min.


AEC-Q200

Not Applicable


Lead Length / Package Type

25mm for Bulk

|Z| vs. Freq. Characteristic

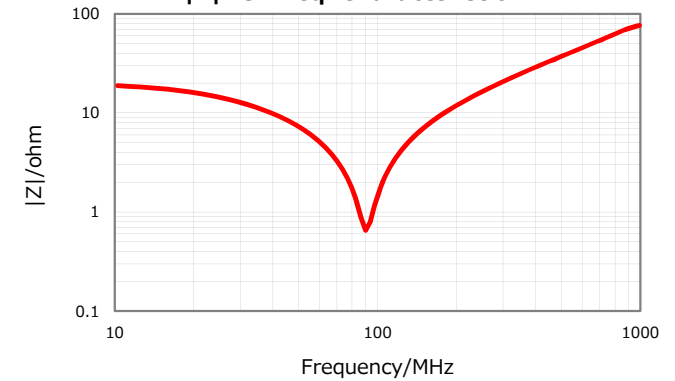

Temperature Characteristic

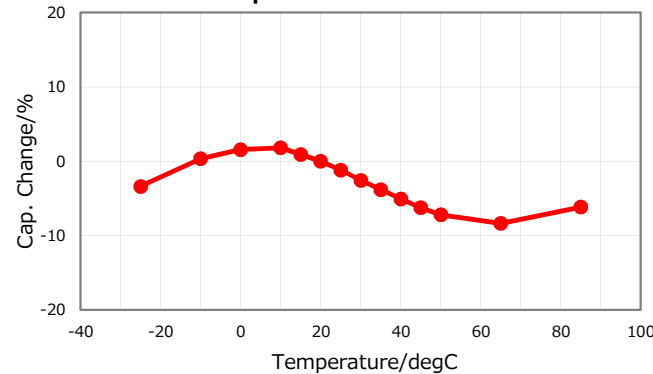

Leak Current

