

CD45SL2GA470J-NKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature


Commercial Grade (Safety Standard Approved)

Series

CD45 Series

Dimensions

| | |
|---|--------------------|
| D | 8.0mm Max. |
| T | 6.0mm Max. |
| F | 10.0mm +2.0,-1.0mm |
| d | 0.6mm +/-0.05mm |
| ℓ | 5.0mm +/-1.0mm |

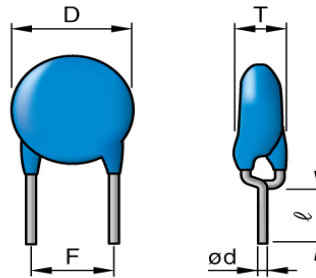

Temperature Characteristic

SL(+350 to -1000ppm/degC)

Rated Voltage

400Vac

Withstanding Voltage

4000Vac

Capacitance

47pF

Capacitance Tolerance

+/-5%

Dissipation Factor

0.5% Max.

Insulation Resistance

10000Mhorm Min.

AEC-Q200

Not Applicable

Lead Length / Package Type

5mm for Bulk

