

# CD45SL2GA470JYNKA

--- Disc Type Capacitors with Lead ---



## Application & Main Feature

Commercial Grade ( Safety Standard Approved )

## Series

CD Series

## Dimensions

D	8.0mm Max.
T	7.0mm Max.
F	10.0mm +2.0,-1.0mm
d	0.6mm +/-0.05mm
ℓ	5.0mm +/-1.0mm



## Temperature Characteristic

SL(+350 to -1000ppm/degC)

## Rated Voltage

440Vac

## Withstanding Voltage

4000Vac

## Capacitance

47pF

## Capacitance Tolerance

+/-5%

## Dissipation Factor

0.5% Max.

## Insulation Resistance

10000Mohm Min.


## AEC-Q200

Not Applicable


## Lead Length / Package Type

5mm for Bulk

## |Z| vs. Freq. Characteristic

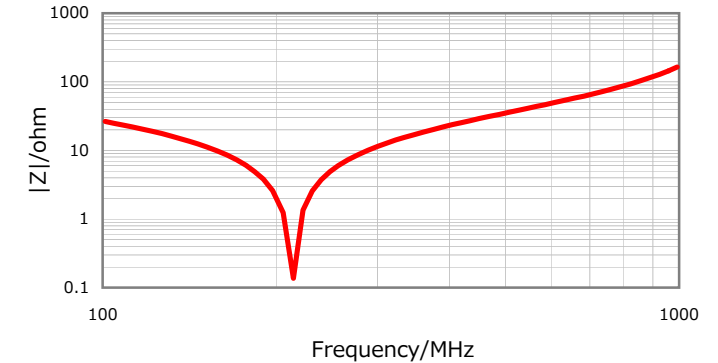

## Temperature Characteristic

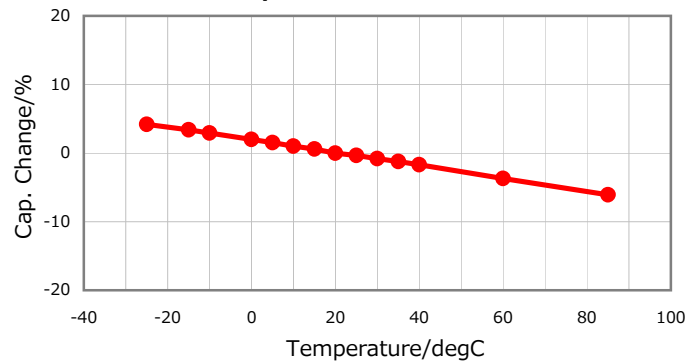

## Leak Current

