

CS45-B2GA221K-NKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature


Commercial Grade (Safety Standard Approved)

Series

CS45 Series

Dimensions

D	6.5mm Max.
T	5.0mm Max.
F	7.5mm +/-1.5mm
d	0.6mm +/-0.05mm
ℓ	5.0mm +/-1.0mm

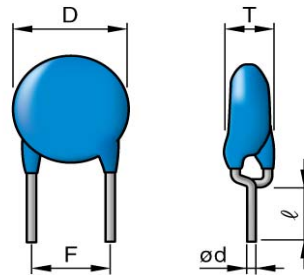

Temperature Characteristic

B(+/-10%)

Rated Voltage

400Vac

Withstanding Voltage

2600Vac

Capacitance

220pF

Capacitance Tolerance

+/-10%

Dissipation Factor

2.5% Max.

Insulation Resistance

10000Mhorm Min.


AEC-Q200

Not Applicable


Lead Length / Package Type

5mm for Bulk

|Z| vs. Freq. Characteristic

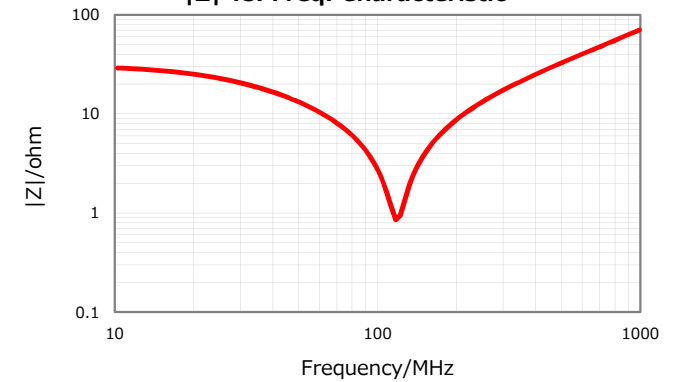

Temperature Characteristic

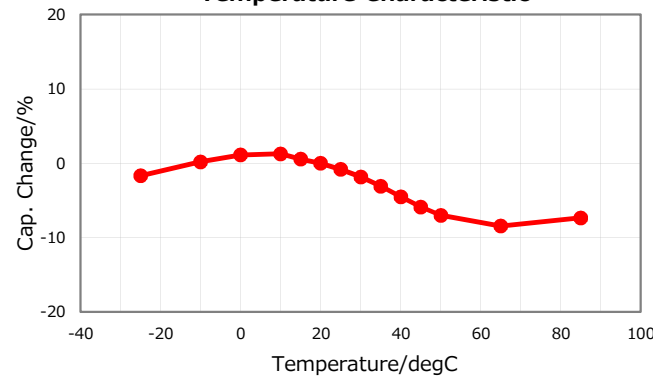

Leak Current

