

# CS45SL2GA220J-GKA

--- Disc Type Capacitors with Lead ---



## Application & Main Feature


Commercial Grade (Safety Standard Approved)

## Series

CS45 Series

## Dimensions

D	7mm Max.
T	5.0mm Max.
F	7.5mm +/-1.5mm
d	0.6mm +/-0.05mm
ℓ	21.0mm Min.

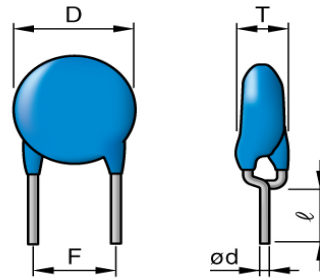

## Temperature Characteristic

SL(+350 to -1000ppm/degC)

## Rated Voltage

400Vac

## Withstanding Voltage

2600Vac

## Capacitance

22pF

## Capacitance Tolerance

+/-5%

## Dissipation Factor

0.5% Max.

## Insulation Resistance

10000Mhorm Min.

## AEC-Q200

Not Applicable

## Lead Length / Package Type

25mm for Bulk

