

CS65ZU2GA102MAVKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature


Automotive Grade (Safety Standard Approved)

Series

CS Series

Dimensions

D 7.0mm Max.
T 7.0mm Max.
F 7.5mm +/-0.8mm
d 0.6mm +/-0.05mm

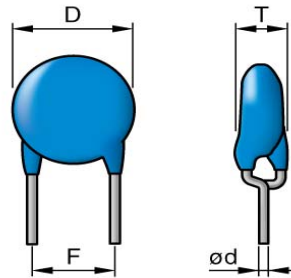

Temperature Characteristic

Z5U(+22,-56%)

Rated Voltage

440Vac

Withstanding Voltage

2600Vac

Capacitance

1nF

Capacitance Tolerance

+/-20%

Dissipation Factor

2.5% Max.

Insulation Resistance

10000Mohm Min.


AEC-Q200

Yes


Lead Length / Package Type

Taping

|Z| vs. Freq. Characteristic

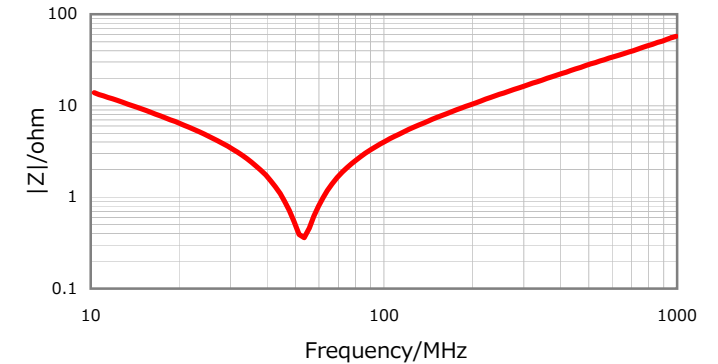

Temperature Characteristic

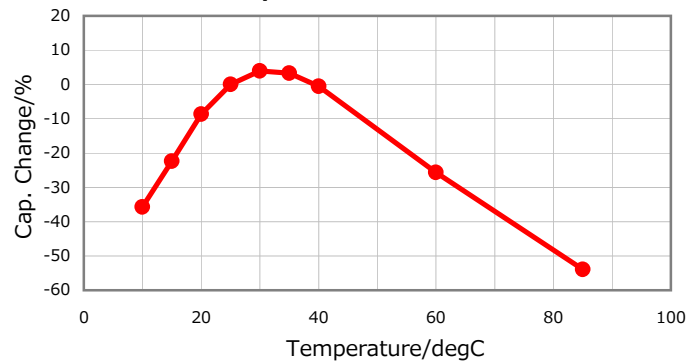

Leak Current

