

CS65ZU2GA102MYNKA

--- Disc Type Capacitors with Lead ---



Application & Main Feature


Commercial Grade (Safety Standard Approved)

Series

CS Series

Dimensions

D	7.0mm Max.
T	5.0mm Max.
F	7.5mm +/-1.5mm
d	0.6mm +/-0.05mm
ℓ	5.0mm +/-1.0mm

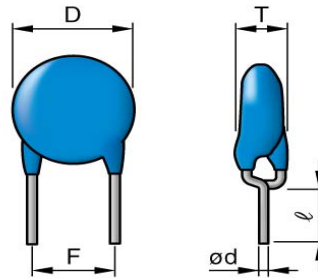

Temperature Characteristic

Z5U(+22,-56%)

Rated Voltage

440Vac

Withstanding Voltage

2600Vac

Capacitance

1nF

Capacitance Tolerance

+/-20%

Dissipation Factor

2.5% Max.

Insulation Resistance

10000Mohm Min.


AEC-Q200

Not Applicable


Lead Length / Package Type

5mm for Bulk

|Z| vs. Freq. Characteristic

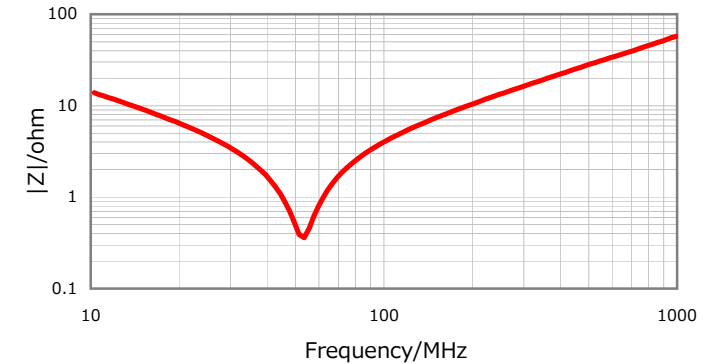

Temperature Characteristic

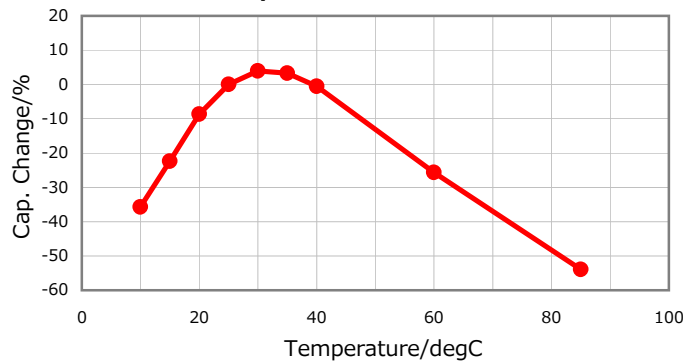

Leak Current

