

FA23NP02W104JNU06




Application

Automotive Grade

Series

FA23

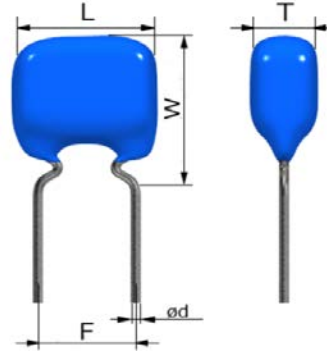

Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +0.8,-0.2mm
d	0.5mm +0.1,-0.03mm

Temperature Characteristic

-55 to 150°C 0+/-30ppm/°C

Rated Voltage

450Vdc

Capacitance

100nF

Capacitance Tolerance

J (+/-5%)

Q Factor





1000 Min.

Insulation Resistance

5Gohm Min

AEC-Q200

Yes

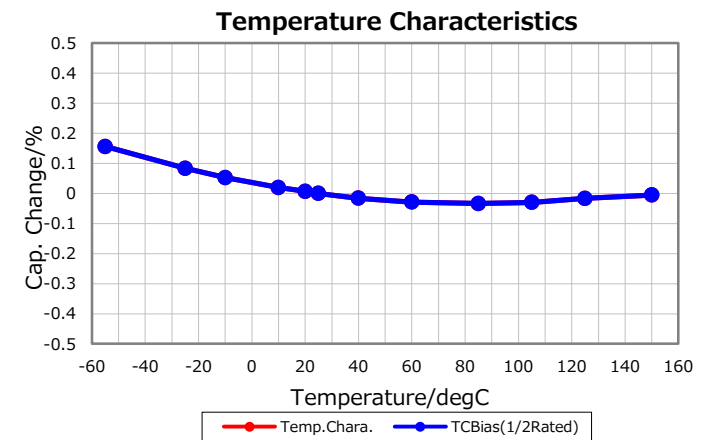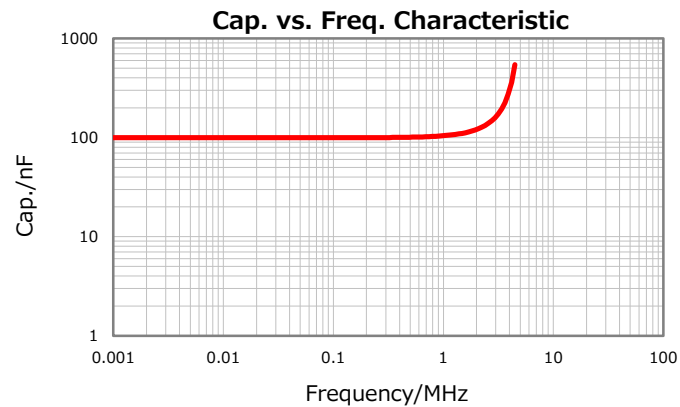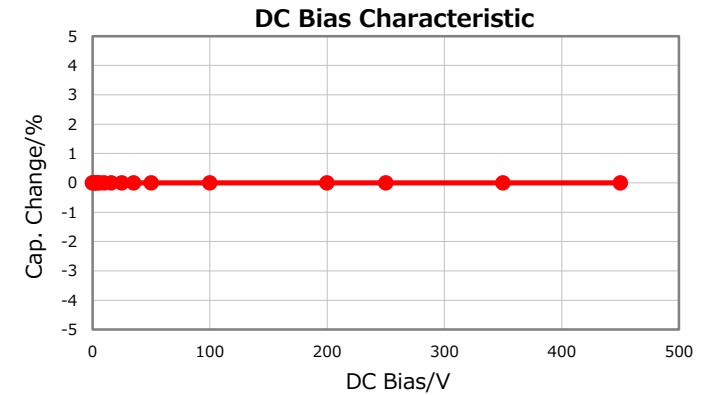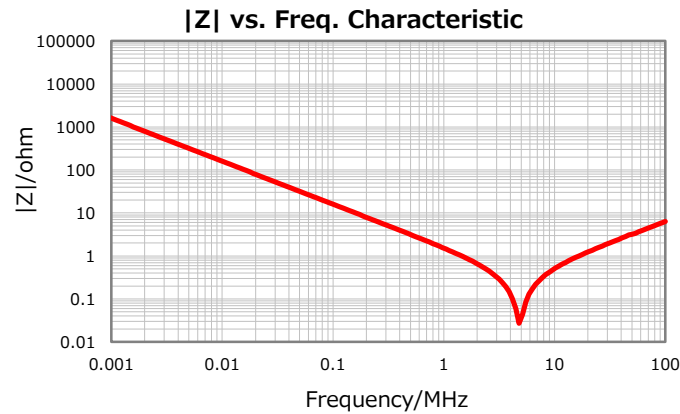

Characterization Sheet (MLCC with Dipped Radial Lead)



All specifications are subject to change without notice.