

FA23X7R2J154KNU06




Application

Automotive Grade

Series

FA23

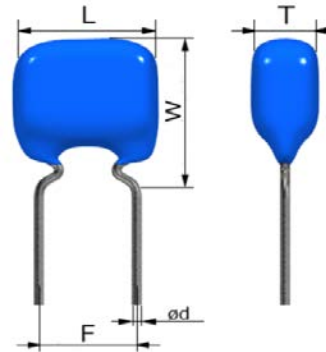

Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +0.8,-0.2mm
d	0.5mm +0.1,-0.03mm

Temperature Characteristic

-55 to 125°C +/-15%

Rated Voltage

630Vdc

Capacitance

150nF

Capacitance Tolerance

K(+/-10%)

Dissipation Factor





3% Max.

Insulation Resistance

3.33Gohm Min

AEC-Q200

Yes

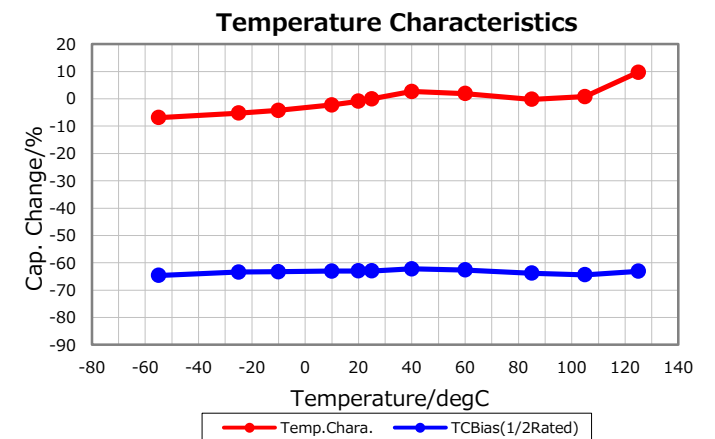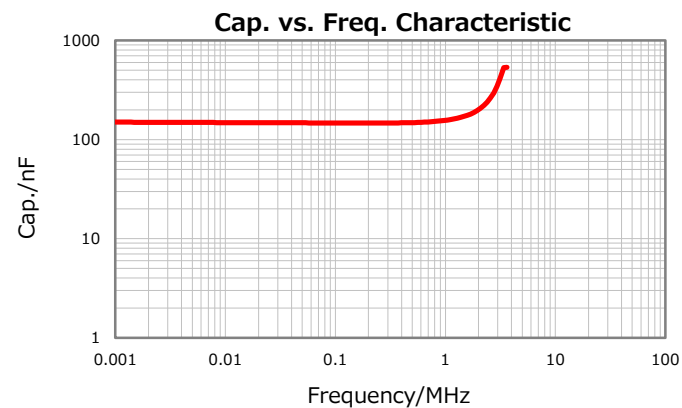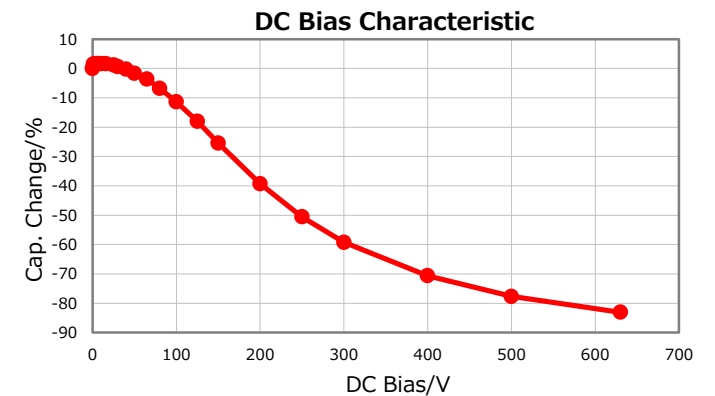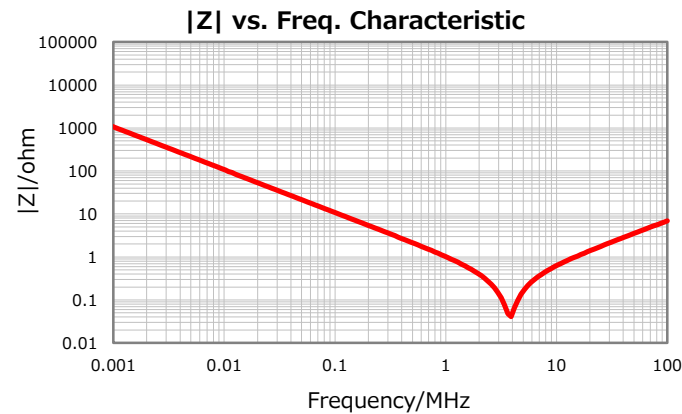

Characterization Sheet (MLCC with Dipped Radial Lead)



All specifications are subject to change without notice.

July 27, 2018