

FA23X7T2E225KNU00




Application

Automotive Grade

Series

FA23

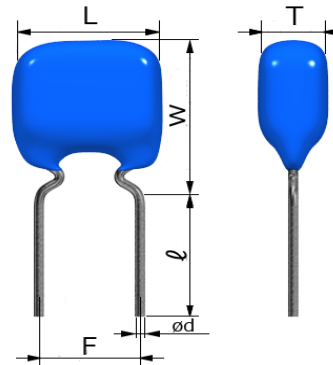

Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +/-1mm
d	0.5mm +0.1,-0.03mm
l	7mm +/-2mm

Temperature Characteristic

-55 to 125°C +22,-33%

Rated Voltage

250Vdc

Capacitance

2.2uF

Capacitance Tolerance

K(+/-10%)

Dissipation Factor

2.5% Max.

Insulation Resistance

227Mohm Min.

AEC-Q200

Yes

