

Application

Automotive Grade

Series

FA28



Dimensions

- L 4mm Max.
- W 5.5mm Max.
- T 2.5mm Max.
- F 5mm +0.8,-0.2mm
- d 0.5mm +0.1,-0.03mm

Temperature Characteristic

-55 to 150°C +/-15%

Rated Voltage

25Vdc

Capacitance

220nF

Capacitance Tolerance

+/-10%

Dissipation Factor

3% Max.


Insulation Resistance

2272Mohm Min.


AEC-Q200

Yes

|Z| vs. Freq. Characteristic

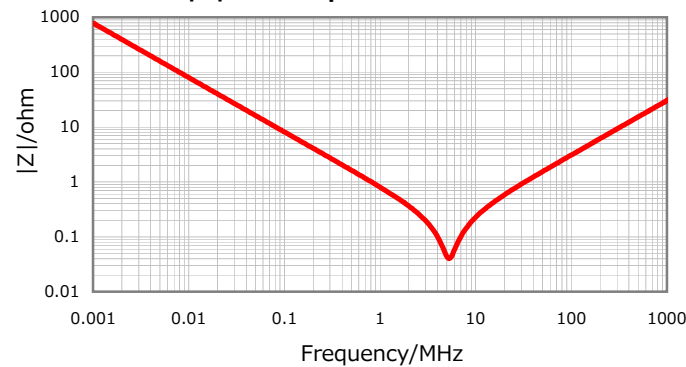

DC Bias Characteristic

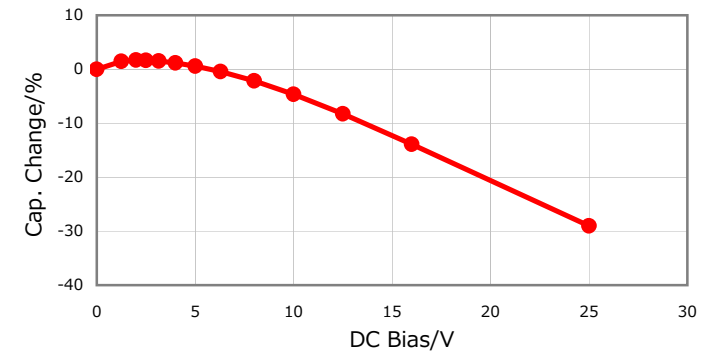

Cap. vs. Freq. Characteristic

