

# FG23C0G2W104JNT00




## Application

Commercial Grade

## Series

FG23

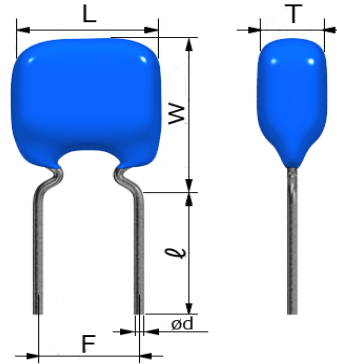

## Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +/-1mm
d	0.5mm +0.1,-0.03mm
l	7mm +/-2mm

## Temperature Characteristic

-55 to 125°C 0+/-30ppm/°C

## Rated Voltage

450Vdc

## Capacitance

100nF

## Capacitance Tolerance

J (+/-5%)

## Q Factor

1000 Min.

## Insulation Resistance

5Gohm Min

## AEC-Q200

No

