

FG23X7R2A475KNT00




Application

Commercial Grade

Series

FG23

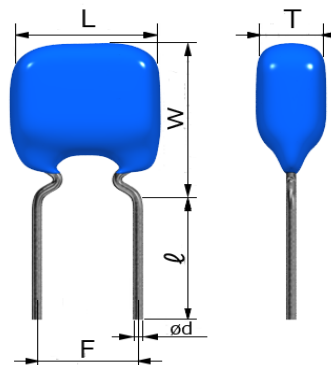

Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +/-1mm
d	0.5mm +0.1,-0.03mm
l	7mm +/-2mm

Temperature Characteristic

-55 to 125°C +/-15%

Rated Voltage

100Vdc

Capacitance

4.7uF

Capacitance Tolerance

K(+/-10%)

Dissipation Factor

3% Max.

Insulation Resistance

106Mohm Min.

AEC-Q200

No

