

FG23X7S2A156MRT06




Application

Commercial Grade

Series

FG23

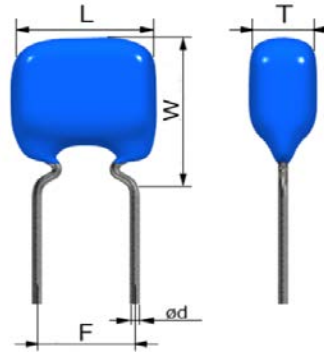

Dimensions

L	8.5mm Max.
W	11mm Max.
T	5.5mm Max.
F	5mm +0.8,-0.2mm
d	0.5mm +0.1,-0.03mm

Temperature Characteristic

-55 to 125°C +/-22%

Rated Voltage

100Vdc

Capacitance

15uF

Capacitance Tolerance

M(+/-20%)

Dissipation Factor





5% Max.

Insulation Resistance

33Mohm Min.

AEC-Q200

No

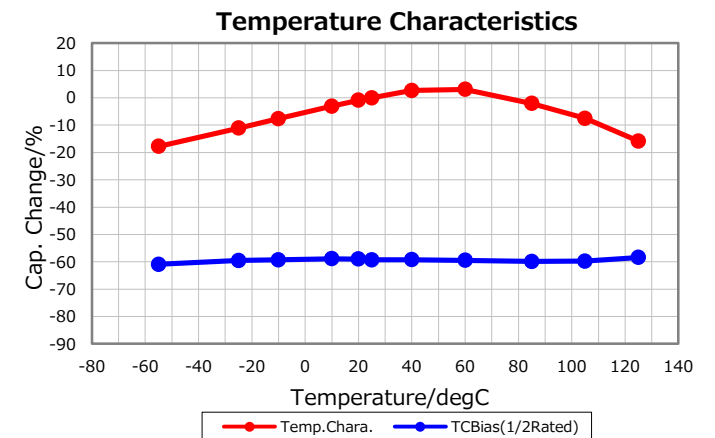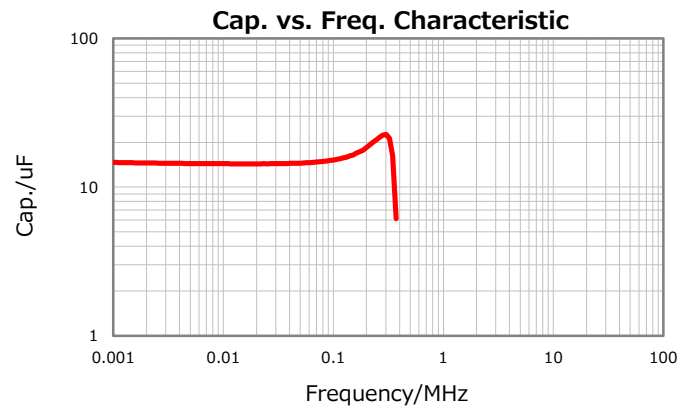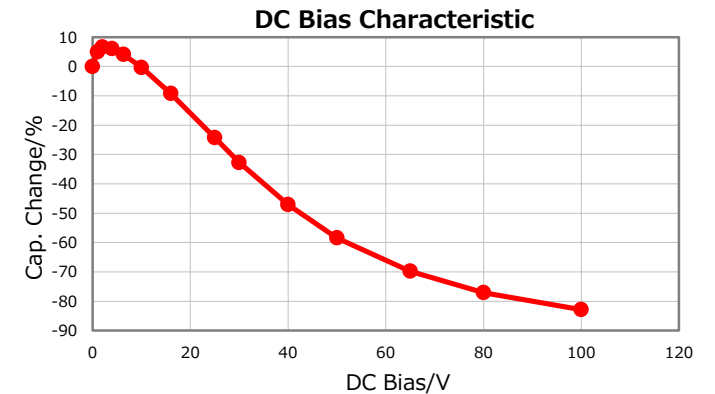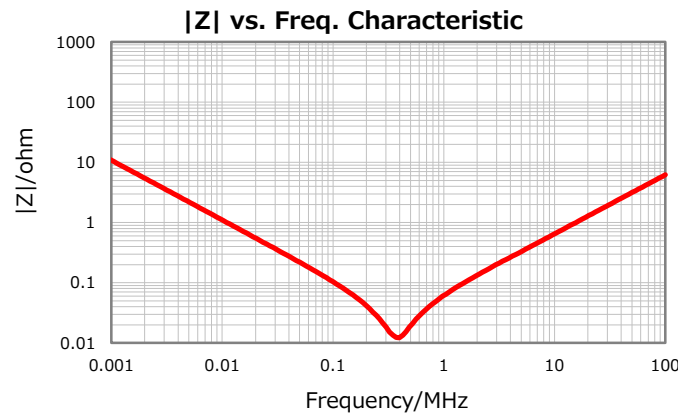

Characterization Sheet (MLCC with Dipped Radial Lead)



All specifications are subject to change without notice.

July 27, 2018