

# FG23X7T2E225KNT06




## Application

Commercial Grade

## Series

FG23

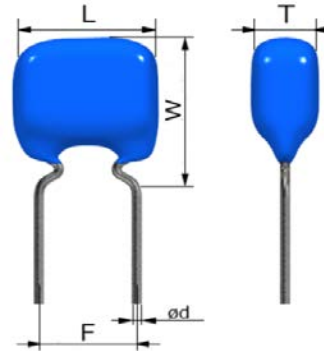

## Dimensions

|   |                    |
|---|--------------------|
| L | 8.5mm Max.         |
| W | 11mm Max.          |
| T | 5.5mm Max.         |
| F | 5mm +0.8,-0.2mm    |
| d | 0.5mm +0.1,-0.03mm |

## Temperature Characteristic

-55 to 125°C +22,-33%

## Rated Voltage

250Vdc

## Capacitance

2.2uF

## Capacitance Tolerance

K(+/-10%)

## Dissipation Factor

2.5% Max.

## Insulation Resistance

227Mohm Min.

## AEC-Q200

No

