

CAA572X7S2A336M640LH

TDK item description : CAA572X7S2A336MT****




Application & Main Feature

Commercial grade (MEGACAP (Low resistance/Inline))

Series

CAA572(5750) [EIA 2220]

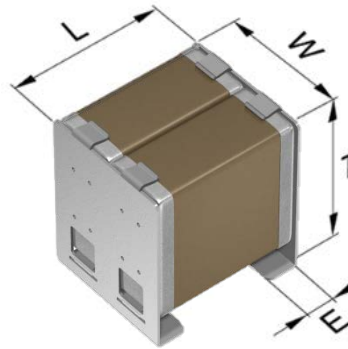

Dimensions

L 6.00±0.50 mm
W 5.00±0.50 mm
T 6.40±0.50 mm
E 1.20±0.20 mm

Temperature Characteristic

X7S (-55 to +125 degC, ±22%)

Rated Voltage

2A (100Vdc)

Capacitance

33µF

Capacitance Tolerance

M (±20%)

DF






5 % max.

Insulation Resistance

15 Mohm min.

AEC-Q200

Not Applicable

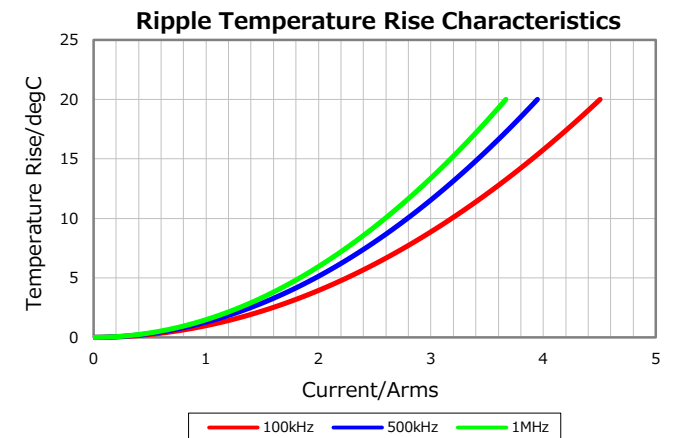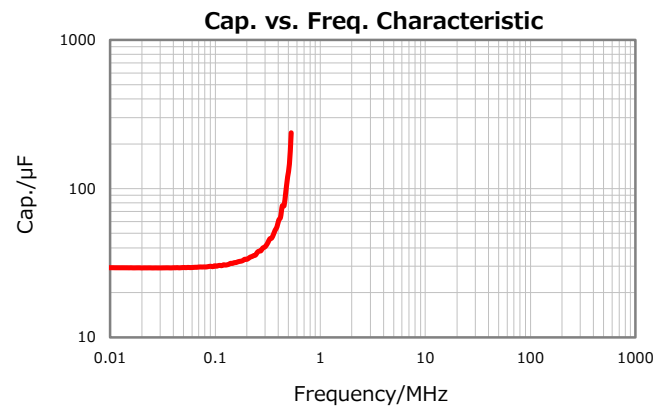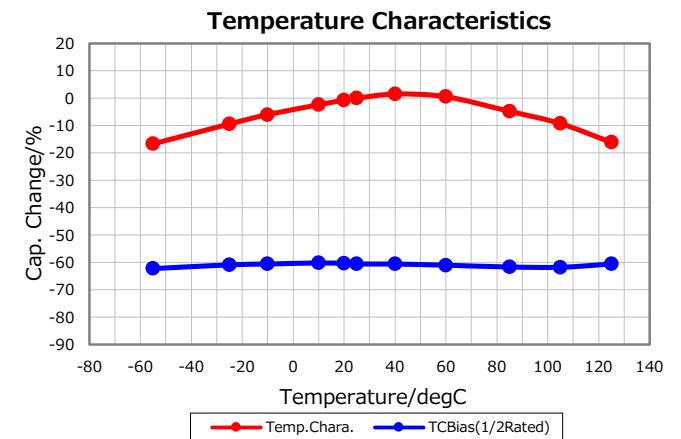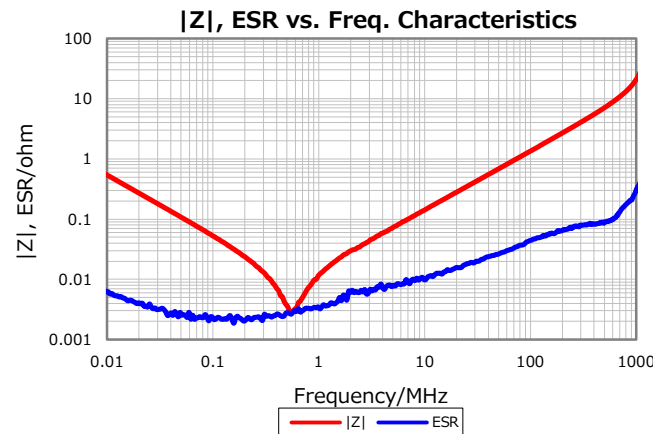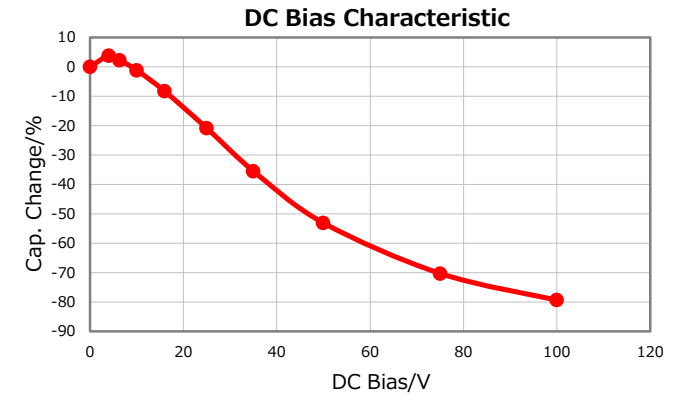

Characterization Sheet (Multilayer Ceramic Chip Capacitors)



All specifications are subject to change without notice.

August 20, 2022