

# CKG32KX7R1E106K335AH

TDK item description : CKG32KX7R1E106KT\*\*\*\*




## Application & Main Feature

Commercial grade (MEGACAP)

## Series

CKG32K(3225) [EIA 1210]

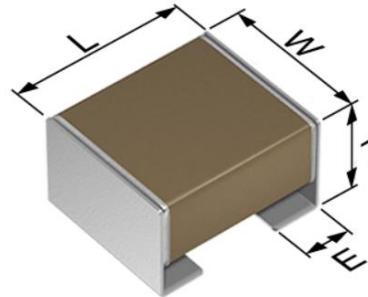

## Dimensions

L 3.60±0.30 mm  
W 2.60±0.30 mm  
T 3.35±0.10 mm  
E 0.80±0.15 mm

## Temperature Characteristic

X7R (-55 to +125 degC, ±15%)

## Rated Voltage

1E (25Vdc)

## Capacitance

10µF

## Capacitance Tolerance

K (±10%)

## DF






5 % max.

## Insulation Resistance

50 Mohm min.

## AEC-Q200

Not Applicable

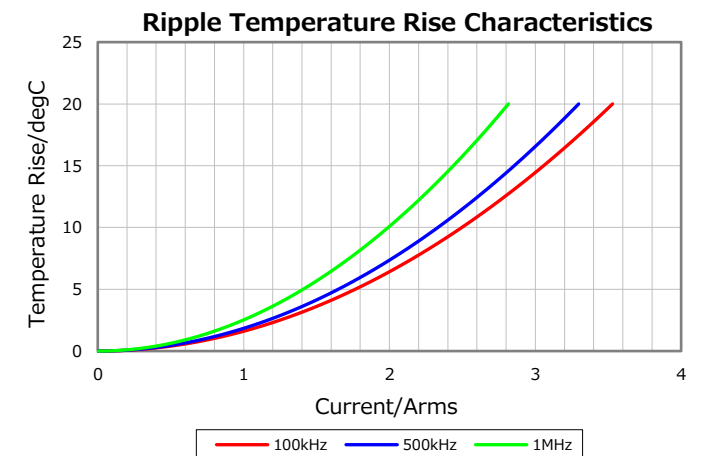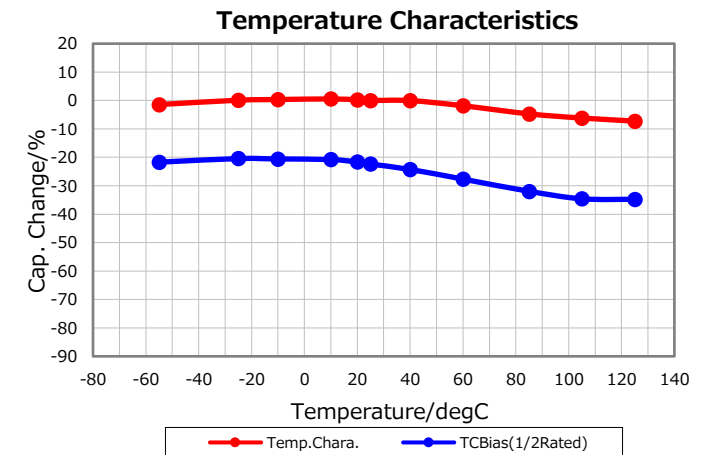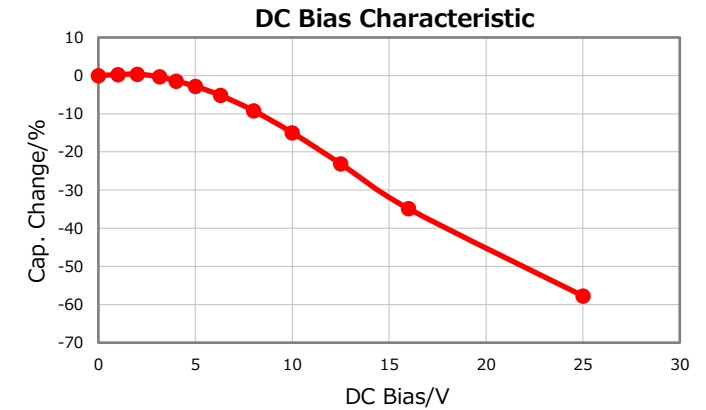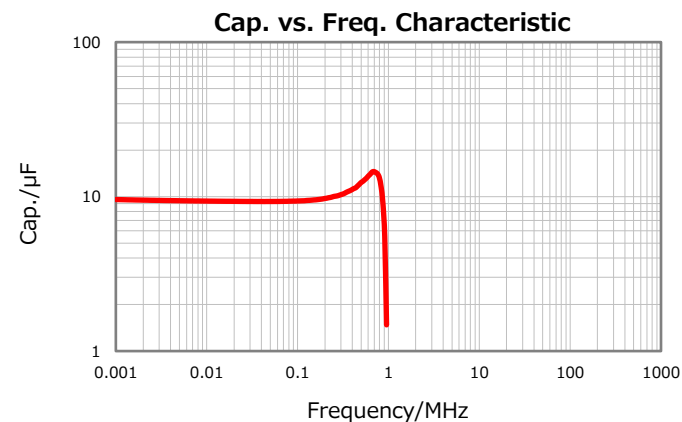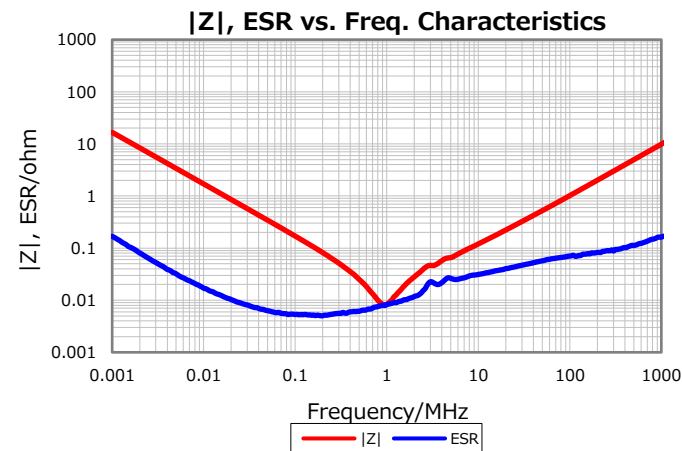

Characterization Sheet ( Multilayer Ceramic Chip Capacitors )



All specifications are subject to change without notice.

April 20, 2022