

# CKG32KX7S2A475M335AH

TDK item description : CKG32KX7S2A475MT\*\*\*




## Application & Main Feature

Commercial grade (MEGACAP)

## Series

CKG32K(3225) [EIA 1210]

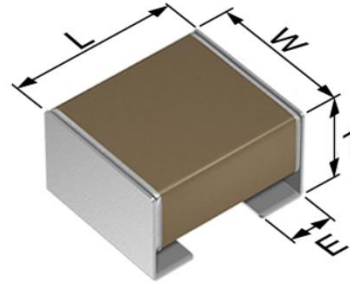

## Dimensions

L	3.60±0.30 mm
W	2.60±0.30 mm
T	3.35±0.10 mm
E	0.80±0.15 mm

## Temperature Characteristic

X7S (-55 to +125 degC, ±22%)

## Rated Voltage

2A (100Vdc)

## Capacitance

4.7µF

## Capacitance Tolerance

M (±20%)

## DF






5 % max.

## Insulation Resistance

106 Mohm min.

## AEC-Q200

Not Applicable

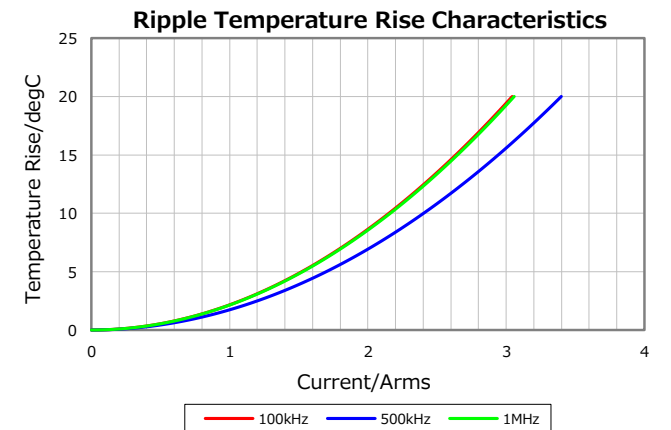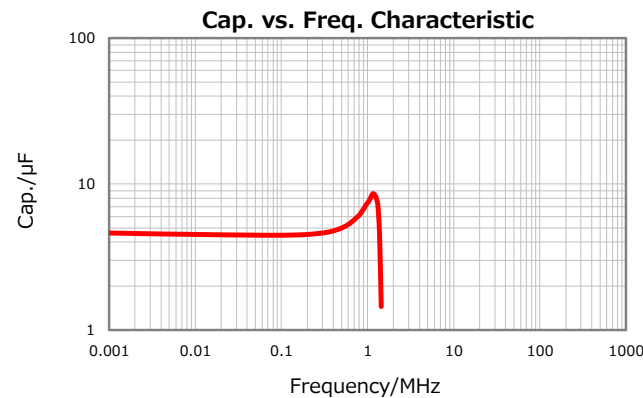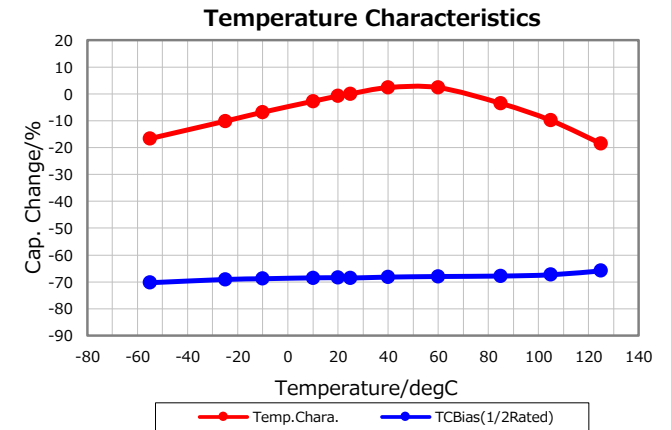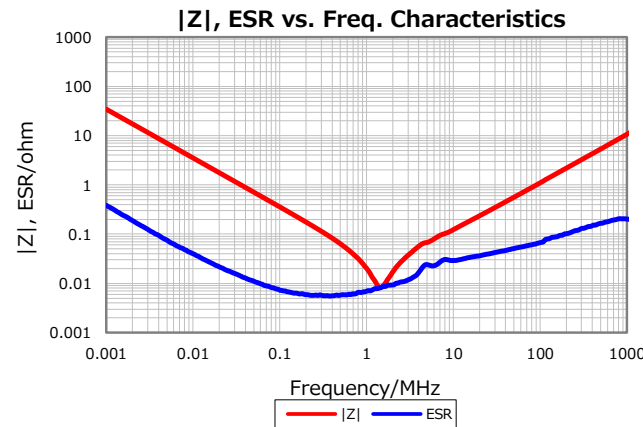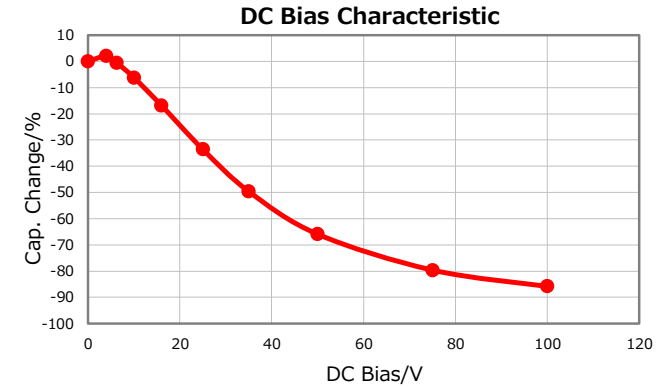

Characterization Sheet ( Multilayer Ceramic Chip Capacitors )



⚠ All specifications are subject to change without notice.

April 14, 2022