

# CKG45KX7R1C106K290JH

TDK item description : CKG45KX7R1C106KT\*\*\*\*




## Application & Main Feature

Commercial grade (MEGACAP)

## Series

CKG45K(4532) [EIA 1812]

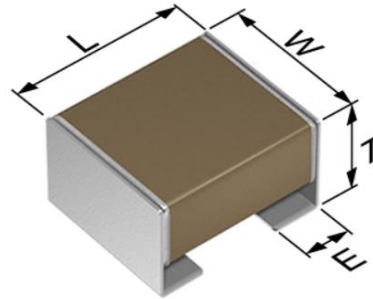

## Dimensions

L 5.00±0.50 mm  
 W 3.50±0.50 mm  
 T 2.90±0.10 mm  
 E 1.10±0.30 mm

## Temperature Characteristic

X7R (-55 to +125 degC, ±15%)

## Rated Voltage

1C (16Vdc)

## Capacitance

10µF

## Capacitance Tolerance

K (±10%)

## DF






5 % max.

## Insulation Resistance

10 Mohm min.

## AEC-Q200

Not Applicable

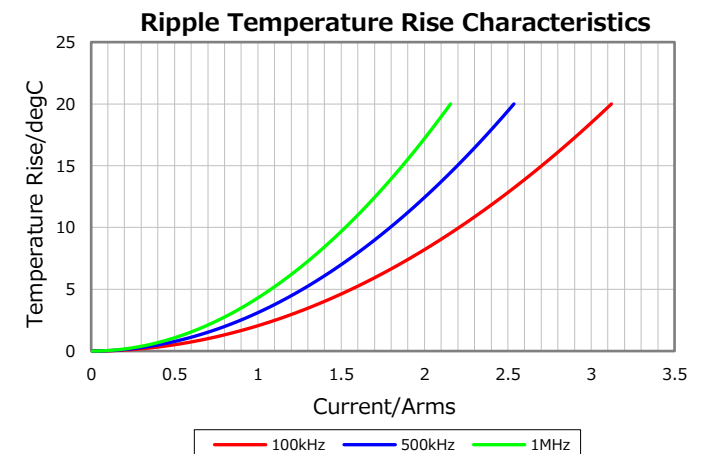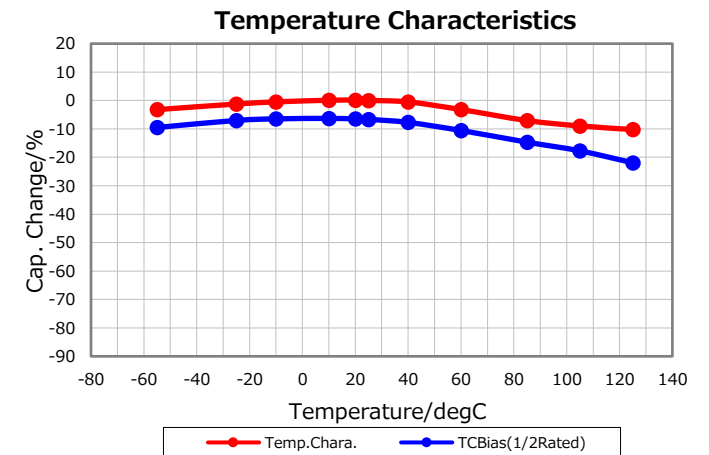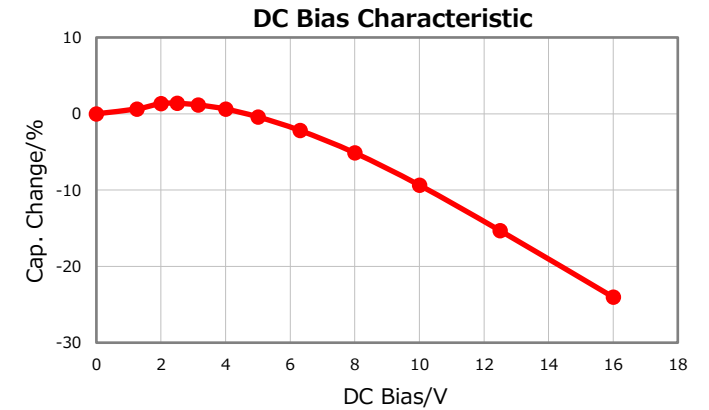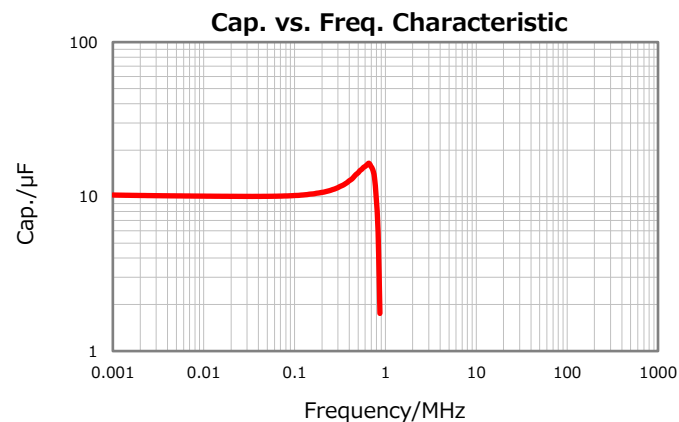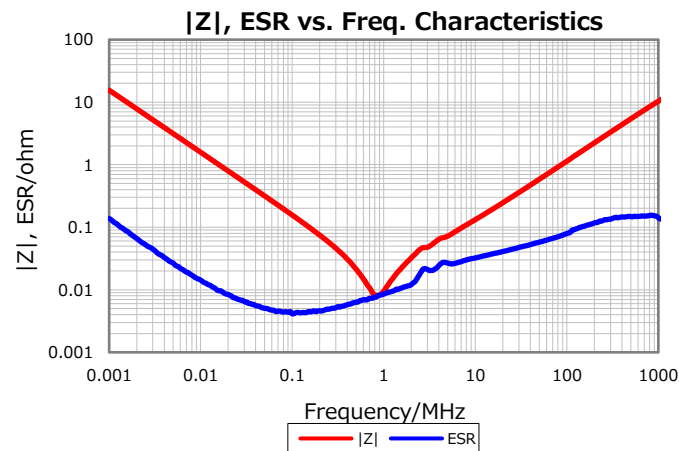

Characterization Sheet ( Multilayer Ceramic Chip Capacitors )



All specifications are subject to change without notice.

April 13, 2022