

CKG45KX7S1H475M290JH

TDK item description : CKG45KX7S1H475MT****




Application & Main Feature

Commercial grade (MEGACAP)

Series

CKG45K(4532) [EIA 1812]

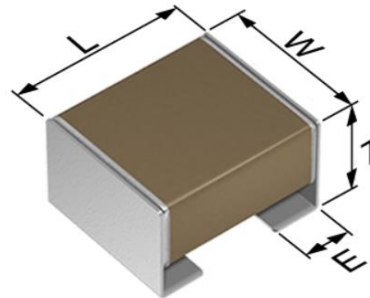

Dimensions

L 5.00±0.50 mm
W 3.50±0.50 mm
T 2.90±0.10 mm
E 1.10±0.30 mm

Temperature Characteristic

X7S (-55 to +125 degC, ±22%)

Rated Voltage

1H (50Vdc)

Capacitance

4.7µF

Capacitance Tolerance

M (±20%)

DF






5 % max.

Insulation Resistance

106 Mohm min.

AEC-Q200

Not Applicable

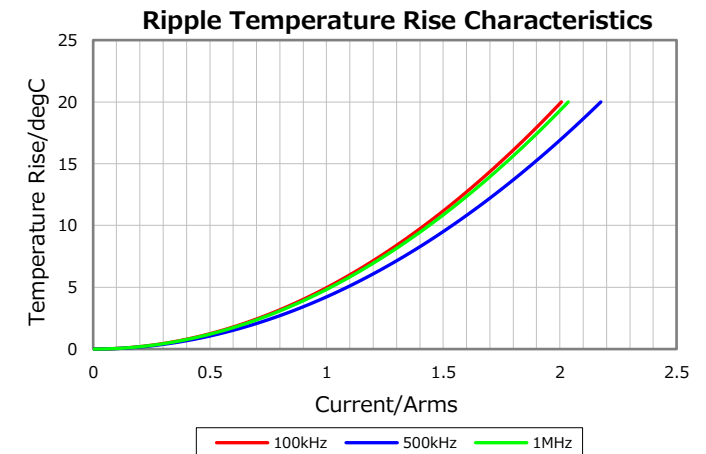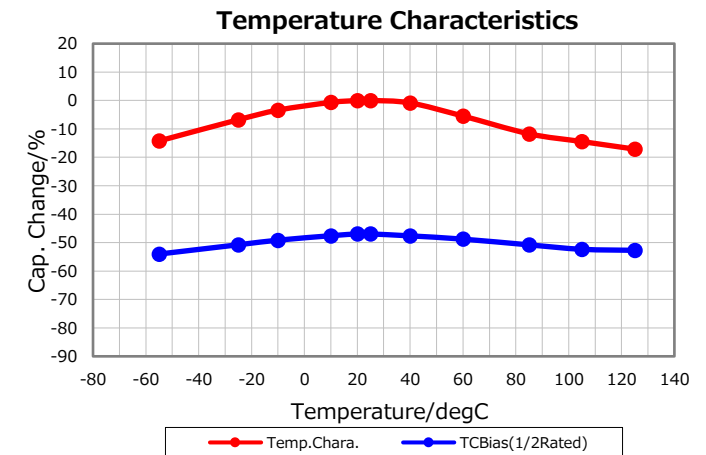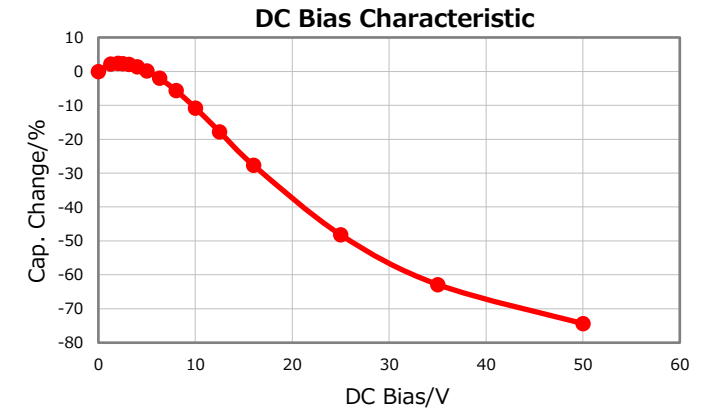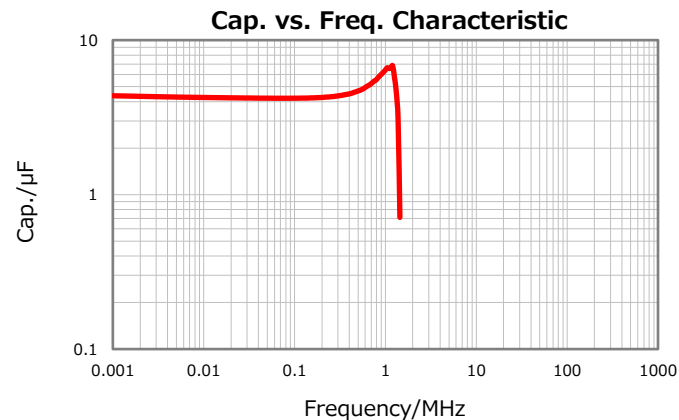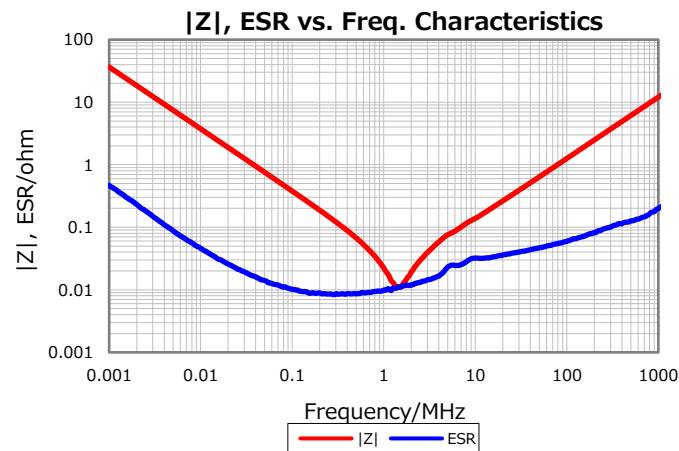

Characterization Sheet (Multilayer Ceramic Chip Capacitors)



All specifications are subject to change without notice.

April 13, 2022