

# CKG57KX7R1H475K335JH

TDK item description : CKG57KX7R1H475KT\*\*\*




## Application & Main Feature

Commercial grade (MEGACAP)

## Series

CKG57K(5750) [EIA 2220]

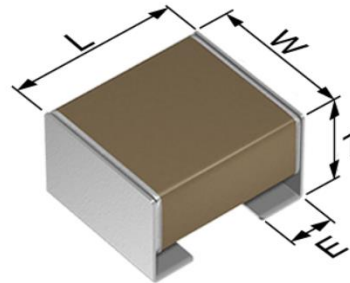

## Dimensions

L 6.00±0.50 mm  
W 5.00±0.50 mm  
T 3.35±0.15 mm  
E 1.60±0.30 mm

## Temperature Characteristic

X7R (-55 to +125 degC, ±15%)

## Rated Voltage

1H (50Vdc)

## Capacitance

4.7µF

## Capacitance Tolerance

K (±10%)

## DF






3 % max.

## Insulation Resistance

106 Mohm min.

## AEC-Q200

Not Applicable

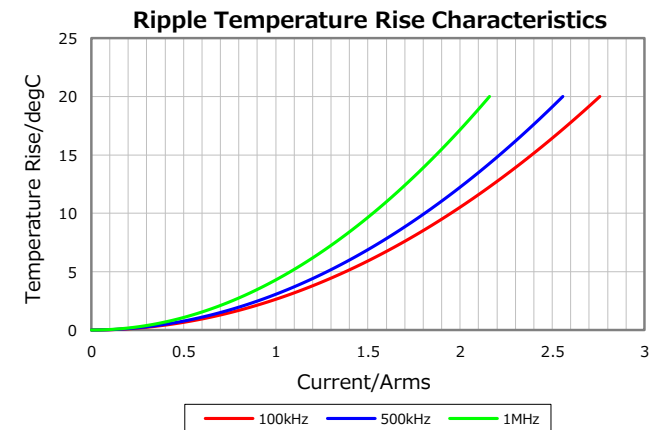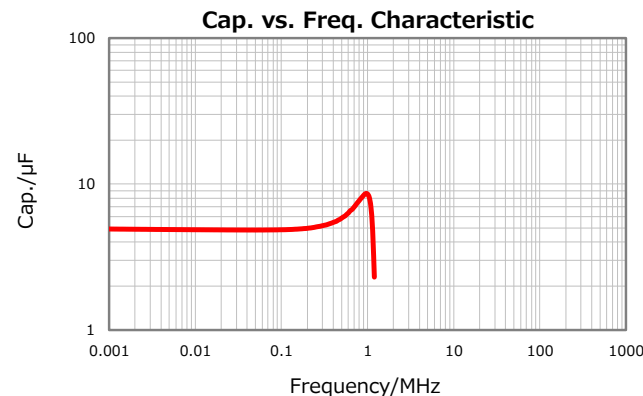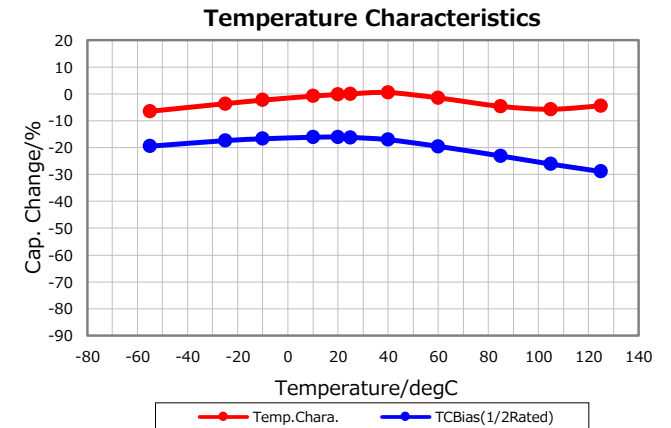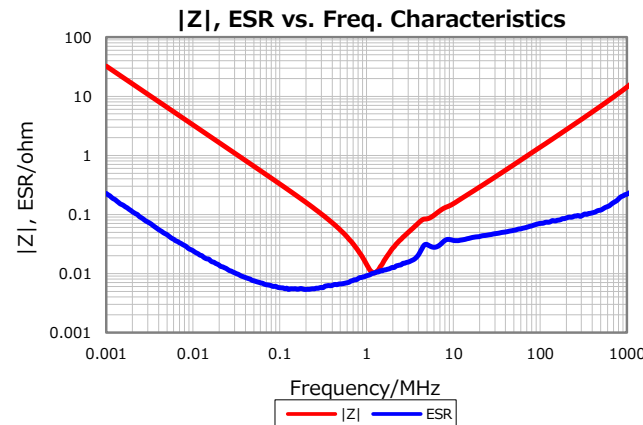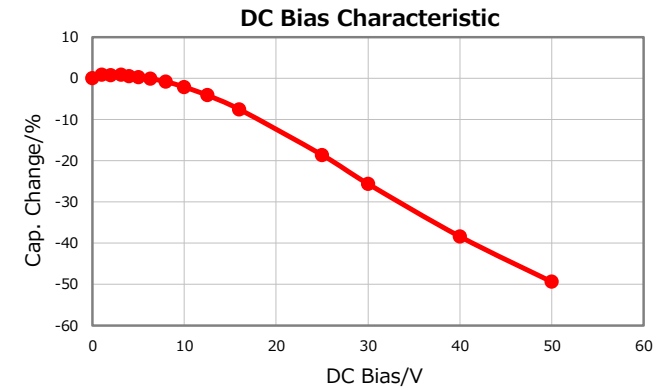

Characterization Sheet ( Multilayer Ceramic Chip Capacitors )



⚠ All specifications are subject to change without notice.

April 8, 2022