

# CKG57KX7R1V476M335JH

TDK item description : CKG57KX7R1V476MT\*\*\*\*




## Application & Main Feature

Commercial grade (MEGACAP)

## Series

CKG57K(5750) [EIA 2220]

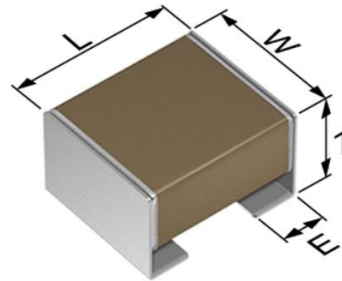

## Dimensions

L	6.00±0.50 mm
W	5.00±0.50 mm
T	3.35±0.15 mm
E	1.60±0.30 mm

## Temperature Characteristic

X7R (-55 to +125 degC, ±15%)

## Rated Voltage

1V (35Vdc)

## Capacitance

47µF

## Capacitance Tolerance

M (±20%)

## DF






5 % max.

## Insulation Resistance

10 Mohm min.

## AEC-Q200

Not Applicable

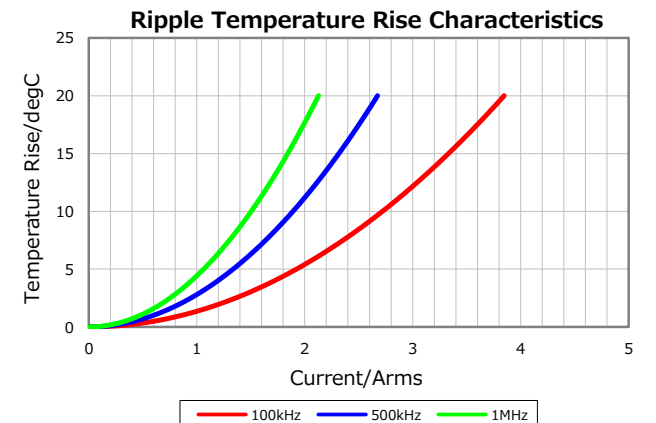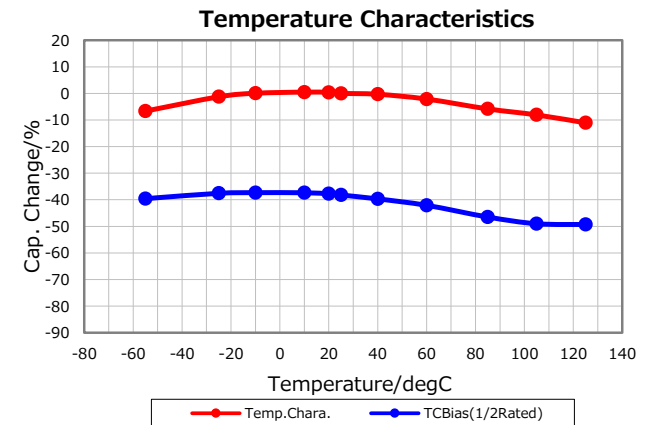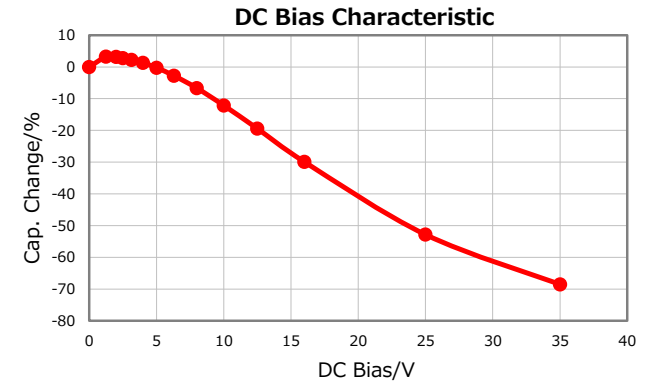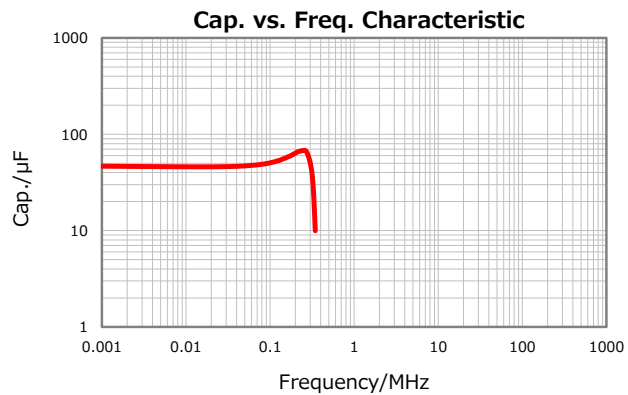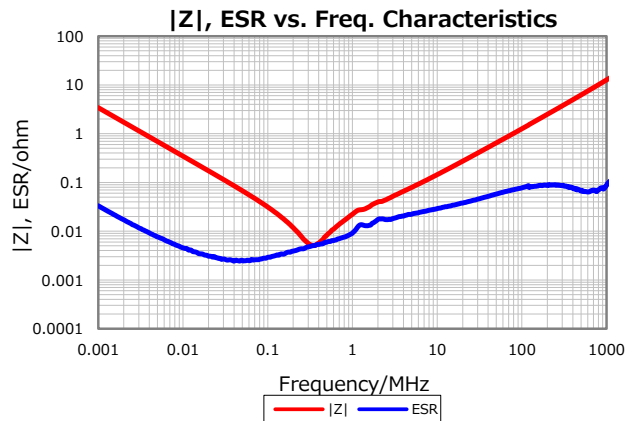

Characterization Sheet (Multilayer Ceramic Chip Capacitors)



All specifications are subject to change without notice.

October 8, 2021