

Certificate



Certificate no.

CU 72150479 01

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
NAGAOKA-SHI, NIIGATA 940-1195
JAPAN

Manufacturing Plant:

Wuxi TDK-Lambda Electronics
Co., Ltd.
No. 6, Xing Chuang Er Lu,
214028 Wuxi, Jiangsu
China

Test report no.: USA-SS 17046691 001

Client Reference: Zhang Zhilong

Tested to: UL 60950-1:2007 R10.14

CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Model Designation: CUS350M-zxxxxxxx

(z=12, 18, 24 or 48; xxxxxxx=F, FN, PG,
2, F2, PG2, S**, 0-9, a-z, A-Z,
other alphanumeric character,
symbol or blank)

7

Rated Voltage: AC 100-240V, 50-60Hz;

Rated Current: 4.0A


Output Ratings: see Appendix (Constr. Data Form)

Protection Class: I

Appendix: 1, 1-12

7

Licensed Test mark:

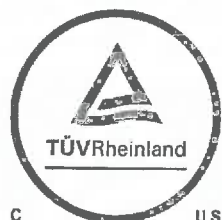

Date of Issue

(day/mo/yr)

08/06/2015

Certificate



Certificate no.

CU 72150479 02

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
NAGAOKA-SHI, NIIGATA 940-1195
JAPAN

Manufacturing Plant:

Zhangjiagang Hua Yang
Electronics Co., Ltd.
Zhao Feng Industrial Zone
Leyu Town, Zhangjiagang
215622 Jiangsu
China

Test report no.: USA-SS 17046691 001

Client Reference: Zhang Zhilong

Tested to:

UL 60950-1:2007 R10.14
CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Additional Manufacturing Plant: see above (K754856)

Licensed Test mark:



Date of Issue

(day/mo/yr)

08/06/2015

Certificate



Certificate no.

CU 72150479 03

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
NAGAOKA-SHI, NIIGATA 940-1195
JAPAN

Manufacturing Plant:

Wuxi TDK-Lambda Electronics
Co., Ltd.
No. 6, Xing Chuang Er Lu,
214028 Wuxi, Jiangsu
China

Test report no.: USA-SS 17046691 002

Client Reference: Zhang Zhilong

Tested to:

UL 60950-1:2007 R10.14

CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Addition:

Model Designation: CUS350M-36xxxxxxx, CME350A-zxxxxxxx
(z = 12, 18, 24, 36 or 48; xxxxxxx = F,
FN, PG, 2, F2, PG2, S**, 0-9, a-z,
A-Z, other alphanumeric character,
symbol or blank)

Appendix: 1, 1-14

Licensed Test mark:



Date of Issue

(day/mo/yr)

06/01/2016

Certificate



Certificate no.

CU 72150479 04

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
Nagaoka-shi, Niigata
940-1195 Japan

Manufacturing Plant:

Sendan Electronics Mfg. Co., Ltd.
1010 Habushin
Nanto-shi, Toyama
939-1756 Japan

Test report no.: USA-SS 17046691 003

Client Reference: Zhang Zhilong

Tested to:


UL 60950-1:2007 R10.14
CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Additional Manufacturing Plant: see above (K756925)

Licensed Test mark:

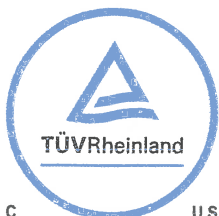

Date of Issue

(day/mo/yr)

20/09/2017

Certificate



Certificate no.

CU 72150479 05

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
Nagaoka-shi, Niigata
940-1195 Japan

Manufacturing Plant:

ALPS Logistics Facilities
Co., Ltd.
593-1 Nishi-Ohashi
Tsukuba-shi, Ibaraki
305-0831 Japan

Test report no.: USA-SS 17046691 003

Client Reference: Zhang Zhilong

Tested to:


UL 60950-1:2007 R10.14
CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Additional Manufacturing Plant: see above (K756924)

Licensed Test mark:

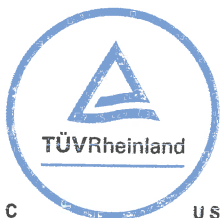

Date of Issue

(day/mo/yr)

20/09/2017

Certificate



Certificate no.

CU 72150479 06

License Holder:

TDK-Lambda Corp.
Nagaoka Technical Center
2704-1 Settaya-machi
Nagaoka-shi, Niigata
940-1195 Japan

Manufacturing Plant:

Wuxi TDK-Lambda Electronics
Co., Ltd.
No. 6, Xing Chuang Er Lu,
214028 Wuxi, Jiangsu
China

Test report no.: USA-SS 17046691 004

Client Reference: Zhang Zhilong

Tested to:

UL 60950-1:2007 R10.14

CAN/CSA-C22.2 NO.60950-1-07+A1:2011+A2:2014

Certified Product: Switching Power Supply

License Fee - Units

Change:

Model Designation: CUS350M-zxxxxxxx, CME350A-zxxxxxxx
(z = 12, 18, 24, 36 or 48; xxxxxxx = F,
FN, PG, 2, F2, PG2, A, S**, 0-9, a-z,
A-Z, other alphanumeric character,
symbol or blank)

Appendix: 1,1-16

Licensed Test mark:



Date of Issue

(day/mo/yr)

14/08/2018