

# Certificate



Certificate no.

TA 50398173 01

**License Holder:**

TDK-Lambda Americas Inc.  
401 Mile of Cars Way, Suite 325,  
National City, CA 91950  
USA

**Manufacturing Plant:**

030-0000414787

**Test report no.:** ZTW1- 50070018 002

**Client Reference:** PW-18122017-TDK-DTM6

**Tested to:**

IEC 60601-1:2005+A1  
EN 60601-1:2006+A11+A1+A12  
IEC 60601-1-6:2010+A1  
EN 60601-1-6:2010+A1  
IEC 62366:2007+A1  
EN 62366:2008+A1

**Certified Product:** AC POWER ADAPTER

**License Fee - Units**

Type Designation	: DTM65PWXXD-ZZZ (TDK-Lambda)	5
XXX stands for	: 050, 120, 150, 190, 240, 280, 360 or 480	1
Z stands for	: blank, 0-9 or A-Z	1
Rated Voltage	: AC 100-240V, 50-60Hz	
Rated Current	: 2-1A	
Outputs	: see Appendix	
max. Power Output	: see Appendix	
max. Ambient Temperature:	50°C	
Protection Class	: I	

This certificate is valid for maximum 5 years.

7

**Licensed Test mark:**



**TÜV Rheinland Taiwan Ltd**

Signature

**Date of Issue**  
(day/mo/yr)

25/01/2018




Dipl.-Ing. (FH) A. Klinker

Appendix to TÜV approved Certificate No.: TA 50398173 01

**Certified Product** : AC POWER ADAPTER  
**Report Number** : 50070018 002  
**Type Designation** : DTM65PWXXXD-ZZZ  
 (XXX = 050, 120, 150, 190, 240, 280, 360 or 480;  
 Z = blank, 0 to 9 or A to Z)

Model name	Output rating		
	Output Voltage [Vdc]	Output Current [A]	Output Power [W]
DTM65PW050D-ZZZ	+5	8.0	40
DTM65PW120D-ZZZ	+12	5.0	60
DTM65PW150D-ZZZ	+15	4.0	60
DTM65PW190D-ZZZ	+19	3.42	65
DTM65PW240D-ZZZ	+24	2.71	65
DTM65PW280D-ZZZ	+28	2.32	65
DTM65PW360D-ZZZ	+36	1.81	65
DTM65PW480D-ZZZ	+48	1.35	65

Date: 25<sup>th</sup> Jan., 2018

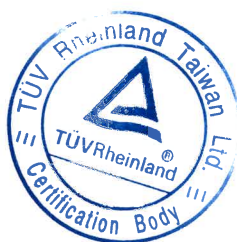

Certification Body



Dipl.-Ing. (FH) A. Klinker